




SNH Hexagon Head Screws

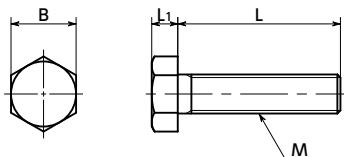

Material/Finish



	SNH
Main Body	SCM435 Ferrosferric Oxide Film (Black)
Strength Class	10.9



- Hexagon head screws compliant with JIS B 1180.


Unit : mm

Part Number ◀1	M (Coarse)		L ◀2											B	L1	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch															
SNH-M5	M5	0.8	8	10	12	20	25	30	35					8	3.5	2.4 - 6.4	20
SNH-M6	M6	1		10	12	16	20	25	30	35	40			10	4	4.4 - 9.6	20
SNH-M8	M8	1.25			12	16	20	25	30	35	40	45	50	13	5.5	10 - 22	20
SNH-M10	M10	1.5				16	20	25	30	35	40	45	50	17	7	22 - 38	10

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

Part Number Specification

 SNH-M8 - 20



1 Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Not Available	Available / Add'l charge	Available / Add'l charge	Not Available