


# SHB-EL / SHBS Hexagon Post



**SUS** Stainless steel

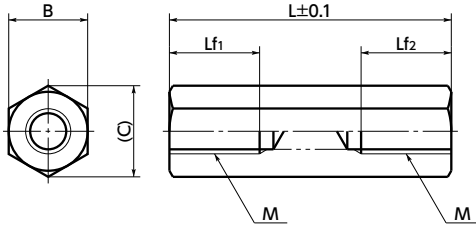

- Hexagon post for both-side female screw.
- Material/Finish **◀1**



	<b>SHB-EL</b> Made of Steel	<b>SHBS</b> Made of Stainless Steel
Main body	SUM22L Electroless Nickel Plating	SUS304

## Dimensions

Unit : mm

Part Number Steel	Part Number Stainless steel	M (Coarse)		B	C	Lf1	Lf2	Mass (g)
		Nominal of Thread <b>◀2</b>	Pitch					
<b>SHB-M3-EL</b>	<b>SHBS-M3</b>	M3	0.5	6	6.9	6	6	2.9 - 9
<b>SHB-M4-EL</b>	<b>SHBS-M4</b>	M4	0.7	7	8.1	8	8	5 - 25
<b>SHB-M5-EL</b>	<b>SHBS-M5</b>	M5	0.8	8	9.2	10	10	5.5 - 40
<b>SHB-M6-EL</b>	<b>SHBS-M6</b>	M6	1	10	11.5	12	12	11 - 98
<b>SHB-M8-EL</b>	<b>SHBS-M8</b>	M8	1.25	13	15	16	16	27 - 168

**SHB-EL** Made of Steel **SHBS** Made of Stainless Steel

Part Number	L (mm) <b>◀3</b>														
	15	20	25	30	35	40	45	50	60	70	80	90	100	120	150
<b>SHB-M3-EL</b>	●	●	●	●	●	●									
<b>SHB-M4-EL</b>		●	●	●	●	●	●	●	●	●	●				
<b>SHB-M5-EL</b>		●	●	●	●	●	●	●	●	●	●	●	●		
<b>SHB-M6-EL</b>			●	●	●	●	●	●	●	●	●	●	●	●	●
<b>SHB-M8-EL</b>					●	●	●	●	●	●	●	●	●	●	●
<b>SHBS-M3</b>	●	●	●	●	●	●									
<b>SHBS-M4</b>		●	●	●	●	●	●	●	●	●	●				
<b>SHBS-M5</b>		●	●	●	●	●	●	●	●	●	●	●	●		
<b>SHBS-M6</b>			●	●	●	●	●	●	●	●	●	●	●	●	●
<b>SHBS-M8</b>					●	●	●	●	●	●	●	●	●	●	●

- Part number specification

**SHB-M4-40-EL**



Cleanroom Wash & Packaging → P.xxxx	Screw Length Adjustment → P.xxxx	Vibration Resistant → P.xxxx	Laser Marking → P.xxxx
Please feel free to contact us	Not Available	Not Available	Available / Add'l charge