




# SNS-J Socket Head Cap Screws

High strength High Specific Strength

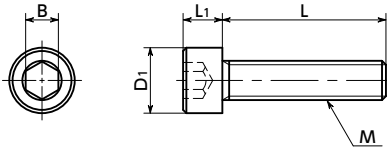

● Material/Finish



SNS-J	
Main Body	SCM435 Ferrosoferric Oxide Film (Black)
Strength Class	12.9

- Conforms to JIS B 1176, ISO 4762, and DIN 912.
- Strength class is 12.9. High strength.
- M3 - M16. Selection from abundant size variations is available to suit the device or equipment.

Unit : mm

Part Number	M (Coarse)		L																D1	L1	B	Mass (g)	Qty per Pack		
	Nominal of Thread	Pitch	4	5	6	8	10	12	16	20	25	30	35	40	45	50	60	70						80	24
<b>SNS-M3</b>	M3	0.5																			5.5	3	2.5	0.65 - 1.5	50
<b>SNS-M4</b>	M4	0.7																			7	4	3	1.5 - 3.6	50
<b>SNS-M5</b>	M5	0.8																			8.5	5	4	2.9 - 6.6	50
<b>SNS-M6</b>	M6	1																			10	6	5	4.8 - 12	50
<b>SNS-M8</b>	M8	1.25																			13	8	6	11 - 26	20
<b>SNS-M10</b>	M10	1.5																			16	10	8	22 - 42	10
<b>SNS-M12</b>	M12	1.75																			18	12	10	41 - 61	5
<b>SNS-M16</b>	M16	2																			24	16	14	97 - 146	1

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part Number Specification

**SNS-M5-12**



<b>1</b> Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Not Available	Available / Add'l charge	Available / Add'l charge	Please feel free to contact us