




# SNPI1S Phillips Cross Recessed Pan Head Machine Screws with Captive Washers

Easy operation **SUS** Stainless steel

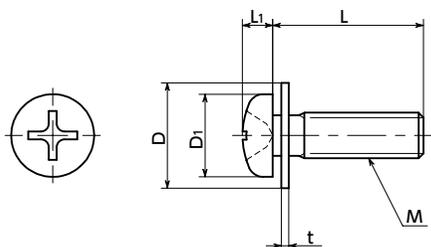

## Material/Finish



	<b>SNPI1S</b>
Screw Body	SUSXM7 (Equivalent to SUS304)
Screw Body Strength Class	A2 - 50
Plain Washer	SUS304

- Stainless steel Phillips cross recessed pan head machine screws with integrated washers.
- Plain washers are integrated into the screws, preventing concerns about fallout issues. (Washer abbreviation: I=1)
- When using a washer in spot facing, workability is improved because the bolt and washer can be mounted and removed at the same time.

## Application

Semiconductor manufacturing equipment / Equipment and device structures / Offshore instruments / General industrial machines

Unit : mm

Part Number <span style="color:red">1</span>	M (Coarse)		L <span style="color:red">2</span>	D <sub>1</sub>	D	L <sub>1</sub>	t	Cross-recessed Socket No.	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch								
<b>SNPI1S-M2.5</b>	M2.5	0.45	5 6 8 10 12 16	4.5	6.5	1.7	0.5	1	0.32 - 0.61	10
<b>SNPI1S-M3</b>	M3	0.5	6 8 10 12 16	5.5	7	2	0.5	2	0.59 - 1.1	10
<b>SNPI1S-M4</b>	M4	0.7	8 10 12 16	7	9	2.6	0.8	2	1.4 - 8.1	10
<b>SNPI1S-M5</b>	M5	0.8	8 10 12 16	9	10	3.3	1	2	2.6 - 3.6	10

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

## Part Number Specification

### SNPI1S-M3 - 10



<b>1</b> Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Not Available	Available / Add'l charge	Not Available