



FST-R Zero point on the left

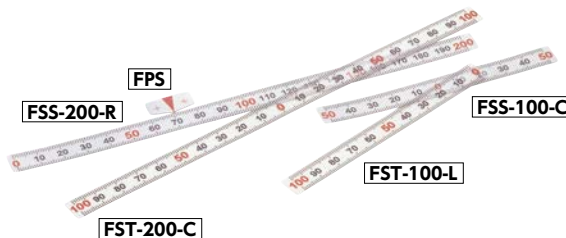

FST-L Zero point on the right

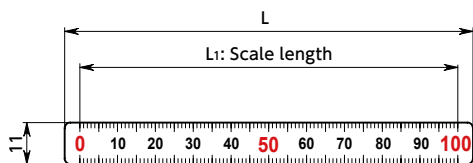

FST-C Center distribution



Thickness: approximately 0.3 mm

- Multiples of 0 and 50 are red.

• Material/Finish



	FST
Main body	Polyester (transparent)

- Sticker type horizontal scale. Use by sticking to machinery and equipment.
- Standardized 100/200/300 mm scale length.
- Made of flexible polyester. Can be stuck to the curved surfaces of posts or shafts, plus can be cut to a desired length for use.
- Corners are rounded. Doesn't come off easily.
- There are 3 types of scales. They can be selected by the symbol of the part number.

Symbol	Scale
R	Zero point on the left
L	Zero point on the right
C	Center distribution

⚠ Precautions for Use

- **FST** Use the scale of the Scale Sticker as a general guideline.
- Thoroughly remove oil and dust on the sticking surface before sticking.

Part Number	L1	L	Mass (g)
FST-100-R	100	108	0.5
FST-200-R	200	208	1
FST-300-R	300	308	1.5
FST-100-L	100	108	0.5
FST-200-L	200	208	1
FST-300-L	300	308	1.5
FST-100-C	100	108	0.5
FST-200-C	200	208	1
FST-300-C	300	308	1.5

Unit : mm

• Related Products

Point Lens **FLE**, which is useful to read the scale, is available.

➔ P.xxxx



Scale Plate / Scale sticker Length Adjustment ➔ P.xxxx

Available / Add'l charge

- Part number specification

FST-200-R

