


SET-NI-ALK / SETS-ALK Hexalobular Socket Head Cap Screws with Extreme Low Profile (Nylon Patch)

SUS Stainless steel  Protrusion

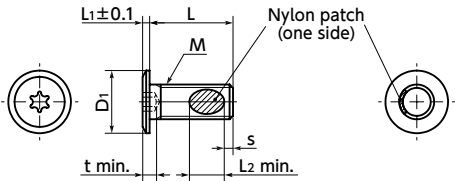

SET-NI-ALK




SET-NI-ALK



SETS-ALK

SETS-ALK

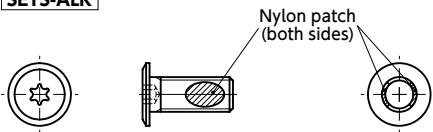

● Application

Reducing the size of equipment and devices / Return and fall prevention of screws

● Material/Finish



	SET-NI-ALK	SETS-ALK
Main Body	SWCH Nickel Plating	SUSXM7 (Equivalent to SUS304)
Nylon Patch	Nylon 11	Nylon 11

- The friction of the nylon adhered to the thread suppresses the return rotation of the thread.
- Even if the tightening force is lost, the return rotation is suppressed, preventing the screws from falling off.
- Hexalobular socket*1 head cap screws with ultra-thin head.
- For space-saving of equipment/devices and applications with limited overhead space.
- Hexalobular socket shapes*1 are designed to withstand high tightening torque. ➡ P.xxxx
- Install and remove with **SKX** Dedicated Wrench or **SKXB** Dedicated Bit and **SRD** Dedicated Magnetic Screwdriver together.
- Use the **SKX-N** hexalobular wrench for extremely limited access spaces for mounting and removing in tight spaces.

*1: The hexalobular shape is prescribed by JIS B 1015: 2008(ISO 10664: 2005)"Hexalobular internal driving feature for bolts and screws".

SET-NI-ALK Made of Steel

Unit : mm

Part Number	M (Coarse)		L						D1	L1	Hexalobular Socket No.	t	s	L2	Max. Tightening Torque (N・m)	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch	1	2	3	4	5	6									
SET-M3-NI-ALK	M3	0.5	6	8	10				7	0.8	6	0.75	1	2.5	0.7	0.43 - 0.6	20
SET-M4-NI-ALK	M4	0.7	6	8	10	12	16	8	0.9	8		0.9	1.4	3.3	2	0.7 - 1.6	20
SET-M5-NI-ALK	M5	0.8		8	10	12	16	9	1	10		1	1.6	4.2	4	1.2 - 2.2	20





- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

SETS-ALK Made of Stainless Steel

Unit : mm

Part Number	M (Coarse)		L												D1	L1	Hexalobular Socket No.	t	s	L2	Max. Tightening Torque (N・m)	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch	1	2	3	4	5	6	8	10	12												
SETS-M2-ALK	M2	0.4	4	5	6	8	10	12							4 ⁰ _{-0.4}	0.5	4	0.4	0.8	1.6	0.12	0.23 - 0.41	20
SETS-M2.6-ALK	M2.6	0.45	4	5	6	8	10	12							6 ⁰ _{-0.5}	0.6	5	0.5	0.9	2.1	0.24	0.22 - 0.46	20
SETS-M3-ALK	M3	0.5			6	8	10	12	16						7 ⁰ _{-0.5}	0.8	6	0.75	1	2.5	0.43	0.45 - 0.9	20
SETS-M4-ALK	M4	0.7			6	8	10	12	16	20	25				8 ⁰ _{-0.5}	0.9	8	0.9	1.4	3.3	1	0.72 - 2.4	20
SETS-M5-ALK	M5	0.8				8	10	12	16	20	25	30			9 ⁰ _{-0.5}	1	10	1	1.6	4.2	2	1.3 - 4.4	20
SETS-M6-ALK	M6	1				8	10	12	16	20	25	30	35	40	12 ⁰ _{-0.6}	1.2	20	1.2	2	5	3.5	2 - 8.7	20

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

1 Individual Sales ➡ P.xxxx	 Cleanroom Wash & Packaging ➡ P.xxxx	 Screw Length Adjustment ➡ P.xxxx	 Vibration Resistant ➡ P.xxxx	 Modification process for captive use ➡ P.xxxx
Available / Add'l charge	S.S. only / Add'l charge	Not Available	Not Available	Not Available

● Related Products

SKX Hexalobular Wrench



SKX-N Hexalobular Wrench for Extremely Limited Access Spaces



SKXB Hexalobular Short Bit



SRD Magnet Screwdriver



● Part number specification

SET-M3-8-NI-ALK

1 2 1