




SRWS Triwing Pan Head Machine Screws

WEB Selection Tool
 WEB CAD Download
 Tamper Resistance
 SUS Stainless steel

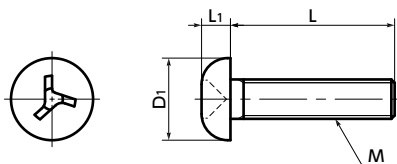

● Part number specification

SRWS-M5-16



Order in number of packs.
The minimum order is 1 piece. → P.xxxx

- This prevents mounting and removing with regular tools.
- Install and remove with **SRWB** Dedicated Bits and **SRD** Dedicated Magnetic Screwdriver together.

● Application

Machinery / Tools / Equipment / Devices disassembly prevention/ Tampering prevention / Theft prevention for outdoor facilities / Security measures / Safety measures

● Material/Finish



	SRWS
Main Body	Equivalent to SUS304
Strength Class	Equivalent to A2-50

Unit : mm

Part Number	M (Coarse)		L					D1	L1	Bit Part No.	Screwdriver Part No.	Mass (g)
	Nominal of Thread	Pitch	6	8	10	12	16					
SRWS-M3	M3	0.5	6	8	10			5.6	1.8	SRWB-2	SRD-6.35	0.54 - 0.7
SRWS-M4	M4	0.7		8	10	12		8.2	2.9	SRWB-4	SRD-6.35	1.5 - 1.9
SRWS-M5	M5	0.8			10	12	16	9.5	3.4	SRWB-5	SRD-6.35	2.8 - 3.5

Part Number	L					Qty per Pack
	6	8	10	12	16	
SRWS-M3	●	●	●			20
SRWS-M4		●	●	●		20
SRWS-M5			●	●	●	20

● The minimum order is 1 piece. → P.xxxx

● **SRWB** Dedicated Bit

Unit : mm

Part Number	L	B	Mass (g)	Qty per Pack
SRWB-2	25.4	6.35	4.8	1
SRWB-4	25.4	6.35	5.2	1
SRWB-5	25.4	6.35	5.6	1

SRWB




● **SRD** Dedicated Magnet Screwdriver

Unit : mm

Part Number	L	B	Mass (g)	Qty per Pack
SRD-6.35	210	6.35	98	1

SRD

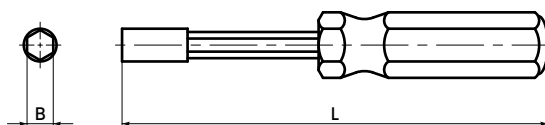

Individual Sales → P.xxxx
 Cleanroom Wash & Packaging → P.xxxx
 Screw Length Adjustment → P.xxxx
 Vibration Resistant → P.xxxx
 Modification process for captive use → P.xxxx
 Available / Add'l charge Available / Add'l charge Available / Add'l charge Available / Add'l charge Available / Add'l charge