
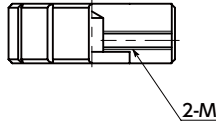
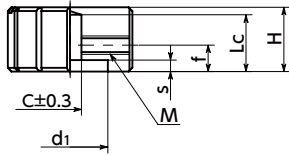
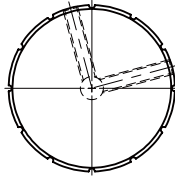


EAT-22  
EAT-27  
EAT-33

EAT-44

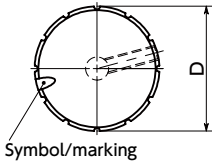

- **EAT-22** **EAT-27** **EAT-33** has symbol marks.

- Material/Finish



	EAT
Main body	Aluminum Alloy Anodized

Unit : mm

Part Number	D	H	d1	s	f	M (Coarse)		Lc	C	Mass (g)
						Nominal of Thread	Pitch			
<b>EAT-22</b>	22	15	16	3	6	1 - M4	0.7	13	6.1	12
<b>EAT-27</b>	27	17	20	3	6	1 - M4	0.7	15	6.1	22
<b>EAT-33</b>	33	17	20	3	6	1 - M4	0.7	15	6.1	33
<b>EAT-44</b>	44	16	20	3	6	2 - M4	0.7	12	6.1	58

- Hex socket set screw is provided.

- Part number specification

**EAT-22**



Cleanroom Wash & Packaging → P.0000	Screw Combination → P.0000	Screw Length Adjustment → P.0000	Vibration Resistant → P.0000	Laser Marking → P.0000
Please feel free to contact us	Not Available	Not Available	Not Available	Available / Add'l charge