




SLHS Socket Head Cap Screws with Low Profile

Protrusion **SUS** Stainless steel

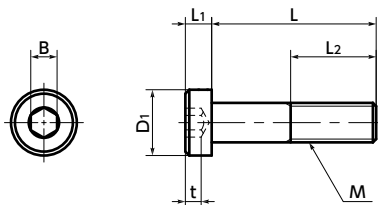

- Socket head cap screws have low head heights.
- Intended for reducing the size of devices and applications with limited overhead space.
- Also, **SVLS** Socket Head Cap Screws with Low Profile with Ventilation Hole is available.
- **SLHS-UCL** with cleanroom washing/cleanroom packing provided are available for some sizes.
- Conforms to DIN 7984.

Application

Reducing the size of equipment and devices

Material/Finish



	SLHS
Main Body	SUSXM7 (Equivalent to SUS304)
Strength Class	A2-50 or more

SLHS SUSXM7

Unit : mm

Part Number 1	M (Coarse)		L 2													D1	L1	B*2	t	L2*1	Max. Torque (N·m)	Mass (g)	Qty per pack								
	Nominal of Thread	Pitch	5	6	8	10	12	16	20	25	30	35	40	45	50									16	20	25	30	35	40	45	50
SLHS-M2	M2	0.4	5	6	8	10	12										3.8	1.3	1.3	0.7	Full Thread	0.18	0.13 - 0.29	50							
SLHS-M2.5	M2.5	0.45	5	6	8	10	12										4.5	1.6	1.5	1	Full Thread	0.36	0.26 - 0.47	50							
SLHS-M3	M3	0.5	5	6	8	10	12	16	20								5.5	2	2	1.5	12(L=20)	0.6	0.5 - 1.2	50							
SLHS-M4	M4	0.7		6	8	10	12	16	20	25							7	2.8	2.5	2.3	Full Thread	1.5	1.1 - 2.8	50							
SLHS-M5	M5	0.8			8	10	12	16	20	25	30	35					8.5	3.5	3	2.7	16(L≥30)	3.1	1.8 - 5.7	50							
SLHS-M6	M6	1				8	10	12	16	20	25	30	35	40	45		10	4	4	3	18(L≥30)	5.3	3.1 - 11	20							
SLHS-M8	M8	1.25					10	12	16	20	25	30	35	40	45	50	13	5	5	3.8	22(L≥35)	12	7.2 - 22	20							
SLHS-M10	M10	1.5							16	20	25	30	35	40	45	50	16	6	6	4.5	32(L≥45)	25	15 - 33	10							

*1: If the "L" value is other than the value in parentheses, the screw is full thread.

*2: The hexagonal width across flat of **SLHS-M10** has been changed from 7 mm to 6 mm.

• When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

Part number specification

SLHS-M5-20



1 Individual Sales Available / Add'l charge	2 Cleanroom Wash & Packaging Available / Add'l charge	3 Screw Length Adjustment Available / Add'l charge	4 Vibration Resistant Available / Add'l charge	5 Modification process for captive use Available / Add'l charge
---	---	--	--	---