


SCBS-GB Clamping Bolts - Knurled Ball - with Reversal Prevention Mechanism



SUS Stainless steel

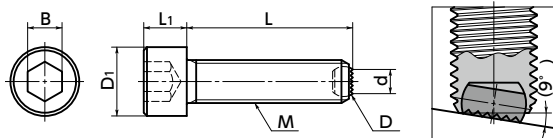

● Material/Finish



	SCBS-GB Made of Stainless Steel
Thread Part	Equivalent to SUS304
Ball	SUS440C (Hardness: 59 - 66 HRC)

● Part Number Specification

SCBS-M6-20-GB



- The ball rotates flexibly . The reversal prevention mechanism ensures secure clamping.
- Even coarse surface such as casting surface can be securely clamped by the knurled ball.
- We also produce products of special specifications, e.g. nominal diameter of thread, length and surface treatment. Please feel free to contact our customer service.

Unit : mm

Part Number	M (Coarse)		L	D1	D	d (Reference Value)	L1	B	Mass (g)
	Nominal of Thread	Pitch							
SCBS-M4-10-GB	M4	0.7	10	7	2.5	1.9	4	3	1.5
SCBS-M4-12-GB	M4	0.7	12	7	2.5	1.9	4	3	1.7
SCBS-M4-16-GB	M4	0.7	16	7	2.5	1.9	4	3	1.9
SCBS-M4-20-GB	M4	0.7	20	7	2.5	1.9	4	3	2.2
SCBS-M4-25-GB	M4	0.7	25	7	2.5	1.9	4	3	2.5
SCBS-M5-12-GB	M5	0.8	12	8.5	3	2.4	5	4	2.9
SCBS-M5-16-GB	M5	0.8	16	8.5	3	2.4	5	4	3.4
SCBS-M5-20-GB	M5	0.8	20	8.5	3	2.4	5	4	3.9
SCBS-M5-25-GB	M5	0.8	25	8.5	3	2.4	5	4	4.4
SCBS-M5-30-GB	M5	0.8	30	8.5	3	2.4	5	4	5
SCBS-M6-16-GB	M6	1	16	10	4	3.1	6	5	5.6
SCBS-M6-20-GB	M6	1	20	10	4	3.1	6	5	6.5
SCBS-M6-25-GB	M6	1	25	10	4	3.1	6	5	7.6
SCBS-M6-30-GB	M6	1	30	10	4	3.1	6	5	8.7
SCBS-M6-40-GB	M6	1	40	10	4	3.1	6	5	11
SCBS-M8-20-GB	M8	1.25	20	13	5.56	4.6	8	6	13.5
SCBS-M8-30-GB	M8	1.25	30	13	5.56	4.6	8	6	17.5
SCBS-M8-35-GB	M8	1.25	35	13	5.56	4.6	8	6	19
SCBS-M8-40-GB	M8	1.25	40	13	5.56	4.6	8	6	21.5
SCBS-M8-50-GB	M8	1.25	50	13	5.56	4.6	8	6	25
SCBS-M10-25-GB	M10	1.5	25	16	7.14	6.1	10	8	26
SCBS-M10-30-GB	M10	1.5	30	16	7.14	6.1	10	8	29
SCBS-M10-40-GB	M10	1.5	40	16	7.14	6.1	10	8	34
SCBS-M10-50-GB	M10	1.5	50	16	7.14	6.1	10	8	39
SCBS-M10-60-GB	M10	1.5	60	16	7.14	6.1	10	8	47
SCBS-M12-30-GB	M12	1.75	30	18	7.94	7.3	12	10	40
SCBS-M12-50-GB	M12	1.75	50	18	7.94	7.3	12	10	56
SCBS-M12-80-GB	M12	1.75	80	18	7.94	7.3	12	10	83
SCBS-M16-40-GB	M16	2	40	24	11.91	10.7	16	14	91
SCBS-M16-60-GB	M16	2	60	24	11.91	10.7	16	14	122
SCBS-M16-80-GB	M16	2	80	24	11.91	10.7	16	14	154

Cleanroom Wash & Packaging	Screw Combination	Screw Length Adjustment	Vibration Resistant
Please feel free to contact us	Not Available	Not Available	Available / Add'l charge